

# CONTINUOUS LED PANEL MOUNT INDICATOR P 22 D BLINKING LED PANEL MOUNT INDICATOR P 22 DFS



Indicator lamps for 22.5 mm mounting hole.

- Guaranteed high protection class (IP 65) to the housing.
- Superior shape, hence high signaling effect on all sides.
- Optimum illumination through the use of multi-chip LED array.
- Easy to mount labels holders available as accessories.
- Simple electrical connection by means of screw terminal.



protection system



operating temperature



**PRODUCT** P 22 D ● I ●

DATA	230 V AC	115 V AC	48 V AC/DC	24 V AC/DC	12 V AC/DC
Rated voltage	230 V AC	115 V AC	48 V AC/DC	24 V AC/DC	12 V AC/DC
Nominal current consumption	25 mA	25 mA	20 mA	80 mA	80 mA

**PRODUCT** P 22 D ● I ● I ●

DATA	230 V AC	115 V AC	48 V AC/DC	24 V AC/DC	12 V AC/DC
Rated voltage	230 V AC	115 V AC	48 V AC/DC	24 V AC/DC	12 V AC/DC
Nominal current consumption	25 mA	25 mA	20 mA	20 mA	20 mA

**PRODUCT** P 22 DFS

DATA	230 V AC	115 V AC	48 V AC/DC	24 V AC/DC
Rated voltage	230 V AC	115 V AC	48 V AC/DC	24 V AC/DC
Nominal current consumption	15–30 mA			




**PRODUCT** P 22 D P 22 DFS

Operating mode	continuous light	1 Hz blinking light
Light source	LED array	
Lens colour	● ● ● ● ●	●
Operating temperature	-25 °C ... +50 °C	
Storage temperature	90 % @ +20 °C	
Protection system (EN 60529)	IP 65 (to housing)	
Service life of the light source	>50,000 hrs	
Mounting	panel-mounting: Ø 22.5 mm	
Connecting terminal	screw terminal 1.5 mm <sup>2</sup>	
Weight	90 g	




**DIMENSIONS**

**PANEL CUT-OUT**

**P 22 D**

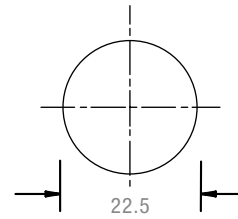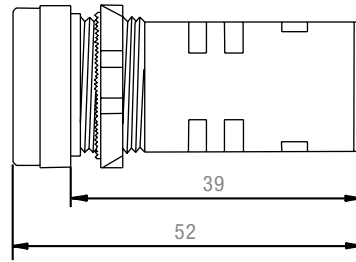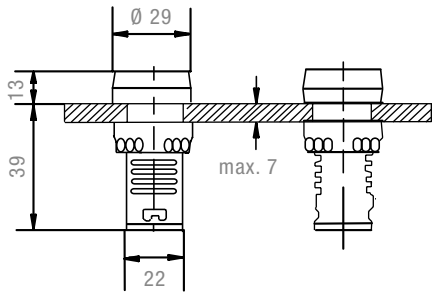


**P 22 DFS**

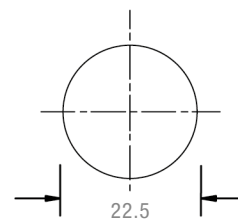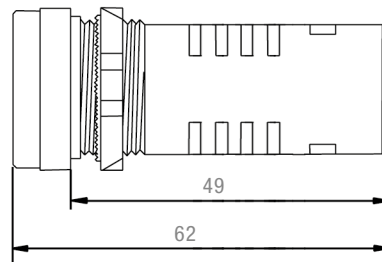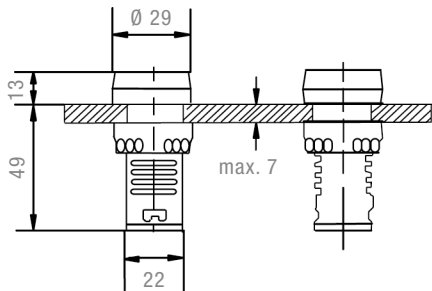



ARTICLE NO.	P 22 D				
LENS COLOUR	230 V AC	115 V AC	48 V AC/DC	24 V AC/DC	12 V AC/DC
○	23273102000	23273152000	23273702000	23273802000	23273852000
●	23273104000	23273154000	23273704000	23273804000	23273854000
●	23273105000	23273155000	23273705000	23273805000	23273855000
●	23273106000	23273156000	23273706000	23273806000	23273856000
●	23273107000	23273157000	23273707000	23273807000	23273857000
ARTICLE NO.	P 22 DFS				
LENS COLOUR	230 V AC	115 V AC	48 V AC/DC	24 V AC/DC	
●	23271105000	23271155000	23271705000	23271805000	

**OPTIONS/ACCESSORIES**

 

25 x 10 mm

 Article no.  
23292000000

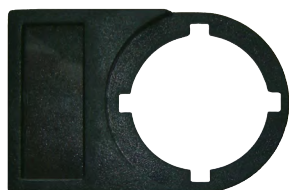

25 x 18 mm

Article no.  
23291000000

